

Part No: HT2-288C

Schedule 80 PVC & CPVC

Hot-Tap Saddle

Desc: 2-1/2X3/4 CPVC HOT TAP SDLE EPDM ZNC BLT

MSRP: 152.64

Part Code: 050

Weight(lbs): 2.053


Weight(kg): 0.931

Weight(gm): 931

Size: 2-1/2 X 3/4 SOC (1"SPG)

Color: GRAY

Material: CPVC

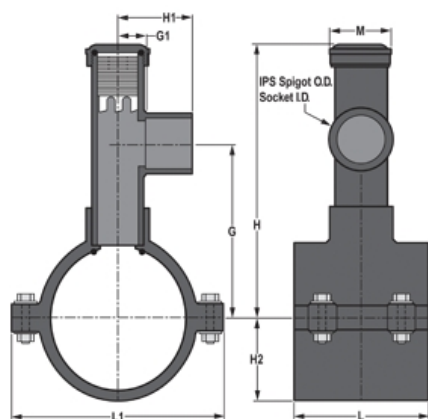

H2 = 1-3/4

M = 2

L1 = 4-1/8

L = 4-1/8

G = 3-15/16

G1 = 1

H = 6-9/16

H1 = 2

Connection Saddle x Socket (Spigot)

Hardware Zinc Plated

O-Ring EPDM

NOTE Not intended To Convey Or
Dispense Water For Human
Consumption Through Drinking
Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

