

Part No: HT2-416

Schedule 80 PVC & CPVC

Hot-Tap Saddle

Desc: 4X3/4 PVC HOT TAP CLAMP SDLE EPDM ZN BLT

MSRP: 121.53

Part Code: 049

Weight(lbs): 1.72


Weight(kg): 0.78

Weight(gm): 780

Size: 4 X 3/4 SOC (1"SPG)

Color: GRAY

Material: PVC

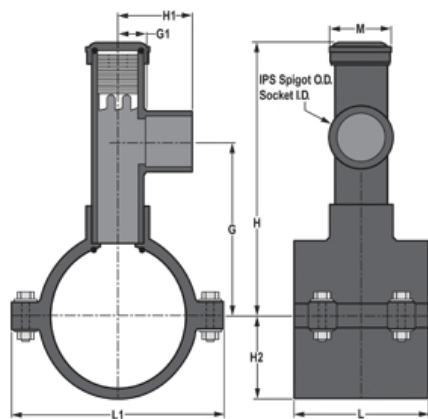

L = 3

G = 4-11/16

G1 = 1

H = 7-5/16

H1 = 2

H2 = 2-5/8

M = 2

L1 = 5-13/16

Connection Saddle x Socket (Spigot)

Hardware Zinc Plated

O-Ring EPDM

NOTE Not intended To Convey Or Dispense Water For Human Consumption Through Drinking Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

