

Part No: HT2-419C

Schedule 80 PVC & CPVC

Hot-Tap Saddle

Desc: 4X1-1/2 CPVC HOT TAP SDLE EPDM ZINC PLTD

MSRP: 355.7

Part Code: 050

Weight(lbs): 3.47


Weight(kg): 1.574

Weight(gm): 1574

Size: 4 X 1-1/2 SOC (2"SPG)

Color: GRAY

Material: CPVC

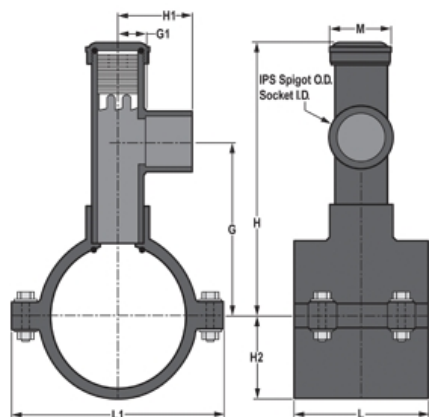

L = 4-1/8 **G** = 5-1/4 **G1** = 1-1/4 **H** = 9-5/8 **H1** = 2-11/16
H2 = 2-5/8 **M** = 2-7/8 **L1** = 5-13/16

Connection Saddle x Socket (Spigot)

Hardware Zinc Plated

O-Ring EPDM

NOTE Not intended To Convey Or
Dispense Water For Human
Consumption Through Drinking
Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

