

Part No: HT2-527

Schedule 80 PVC & CPVC

Hot-Tap Saddle

Desc: 6X1-1/2 PVC HOT TAP SDLE EPDM ZN PLTD BT

MSRP: 227.73

Part Code: 049

Weight(lbs): 4.716


Weight(kg): 2.139

Weight(gm): 2139

Size: 6 X 1-1/2 SOC (2"SPG)

Color: GRAY

Material: PVC

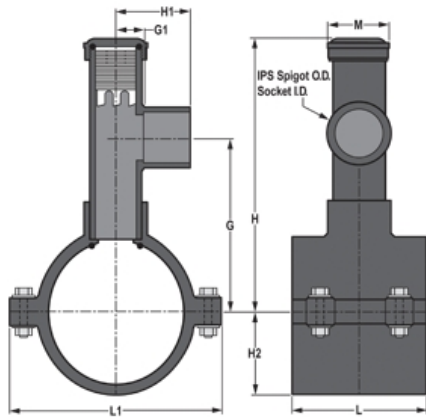

L = 4-1/8 **G** = 6-15/16 **G1** = 1-1/4 **H** = 10-15/16 **H1** = 2-11/16
H2 = 3-13/16 **M** = 2-7/8 **L1** = 8-3/16

Connection Saddle x Socket (Spigot)

Hardware Zinc Plated

O-Ring EPDM

NOTE Not intended To Convey Or Dispense Water For Human Consumption Through Drinking Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

