

Part No: HT2S-248

Schedule 80 PVC & CPVC

Hot-Tap Saddle

Desc: 2X3/4 PVC HOT TAP SADDLE EPDM S/S BOLT

MSRP: 133.88

Part Code: 049

Weight(lbs): 1.091


Weight(kg): 0.495

Weight(gm): 495

Size: 2 X 3/4 SOC(1"SPG)

Color: GRAY

Material: PVC

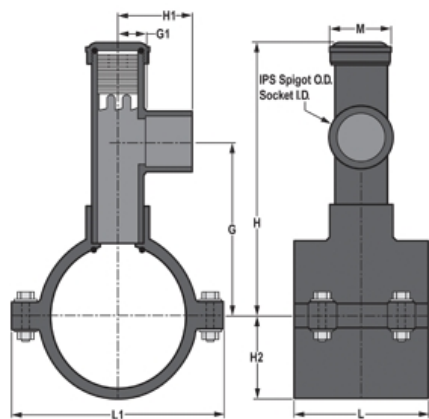

L1 = 3-7/16

G = 3-9/16

G1 = 1

H = 6-3/16

H1 = 2

H2 = 1-1/2

M = 2

L = 2-7/16

Connection Saddle x Socket (Spigot)

Hardware SS316

O-Ring EPDM

NOTE Not intended To Convey Or
Dispense Water For Human
Consumption Through Drinking
Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

