

**Part No:** HT2S-334W

**Schedule 40 White**

**Hot-Tap Saddle**

**Desc:** 3X3/4 PVC HOT TAP SADDLE EPDM S/S BOLT

**MSRP:** 163.79

**Part Code:** 049

**Weight(lbs):** 1.338


**Weight(kg):** 0.607

**Weight(gm):** 607

**Size:** 3 X 3/4 SOC(1"SPG)

**Color:** WHITE

**Material:** PVC

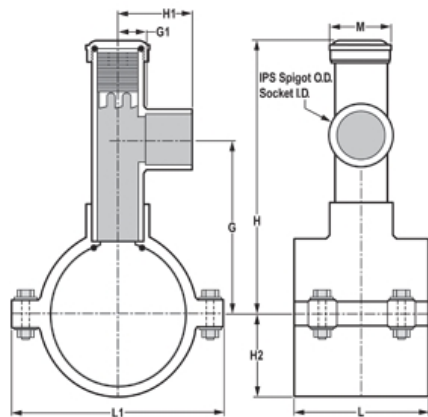

**L** = 3

**G** = 3-15/16

**G1** = 1

**H** = 6-5/8

**H1** = 2

**H2** = 2

**M** = 2

**L1** = 4-3/4

**Connection** Saddle x Socket (Spigot)

**Hardware** SS316

**O-Ring** EPDM

**NOTE** Not intended To Convey Or  
Dispense Water For Human  
Consumption Through Drinking  
Or Cooking

**Cutter** Brass

**Type** Hot-Tap

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

