

Part No: HT2S-337W

Schedule 40 White

Hot-Tap Saddle

Desc: 3X1-1/2 PVC HOT TAP SADDLE EPDM S/S BOLT

MSRP: 314.97

Part Code: 049

Weight(lbs): 2.895


Weight(kg): 1.313

Weight(gm): 1313

Size: 3 X 1-1/2 SOC(2"SPG)

Color: WHITE

Material: PVC

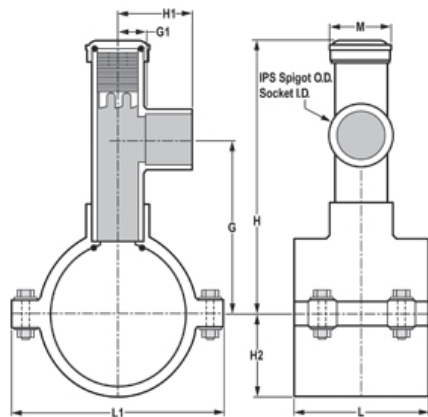

L = 4-1/8

G = 5-1/8

G1 = 1-1/4

H = 9-1/8

H1 = 2-11/16

H2 = 2

M = 2-7/8

L1 = 4-3/4

Connection Saddle x Socket (Spigot)

Hardware SS316

O-Ring EPDM

NOTE Not intended To Convey Or
Dispense Water For Human
Consumption Through Drinking
Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

