

Part No: HT2S-419W

Schedule 40 White

Hot-Tap Saddle

Desc: 4X1-1/2 PVC HOT TAP SADDLE EPDM S/S BOLT

MSRP: 332.93

Part Code: 049

Weight(lbs): 2.884


Weight(kg): 1.308

Weight(gm): 1308

Size: 4 X 1-1/2 SOC(2"SPG)

Color: WHITE

Material: PVC

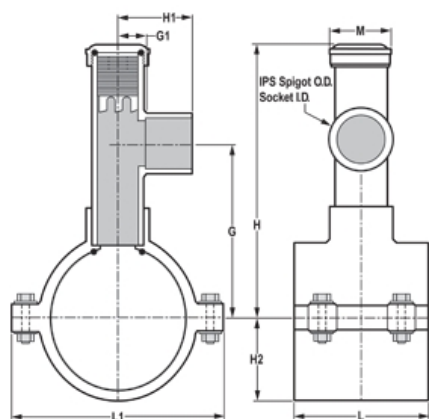

M = 2-7/8

L1 = 5-13/16

L = 4-1/8

G = 5-1/4

G1 = 1-1/4

H = 9-5/8

H1 = 2-11/16

H2 = 2-5/8

Connection Saddle x Socket (Spigot)

Hardware SS316

O-Ring EPDM

NOTE Not intended To Convey Or
Dispense Water For Human
Consumption Through Drinking
Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

