

Part No: HT2S-527W

Schedule 40 White

Hot-Tap Saddle

Desc: 6X1-1/2 PVC HOT TAP SADDLE EPDM S/S BOLT

MSRP: 354.19

Part Code: 049

Weight(lbs): 4.753


Weight(kg): 2.156

Weight(gm): 2156

Size: 6"X 1-1/2"SOC(2"SPG)

Color: WHITE

Material: PVC

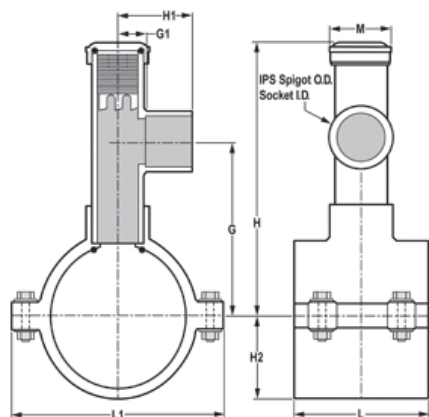

H1 = 2-11/16

H2 = 3-13/16

M = 2-7/8

L1 = 8-3/16

L = 4-1/8

G = 6-15/16

G1 = 1-1/4

H = 10-15/16

Connection Saddle x Socket (Spigot)

Hardware SS316

O-Ring EPDM

NOTE Not intended To Convey Or
Dispense Water For Human
Consumption Through Drinking
Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

