

Part No: HT2S-577C

Schedule 80 PVC & CPVC

Hot-Tap Saddle

Desc: 8X1-1/2 CPVC HOT TAP SDDLE EPDM S/S BOLT

MSRP: 637.27

Part Code: 050

Weight(lbs): 10.027


Weight(kg): 4.548

Weight(gm): 4548

Size: 8"X 1-1/2"SOC(2"SPG)

Color: GRAY

Material: CPVC

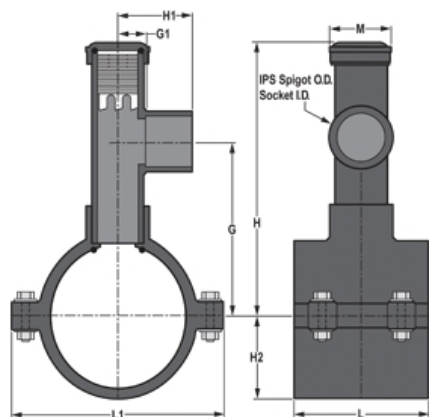

L = 8-1/2

G = 8-1/4

G1 = 1-1/4

H = 12-1/4

H1 = 2-11/16

H2 = 4-7/8

M = 2-7/8

L1 = 10-1/16

Connection Saddle x Socket (Spigot)

Hardware SS316

O-Ring EPDM

NOTE Not intended To Convey Or
Dispense Water For Human
Consumption Through Drinking
Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

