

Part No: HT3-251C

Schedule 80 PVC & CPVC

Hot-Tap Saddle

Desc: 2X1-1/2 CPVC HOT TAP SADDLE FKM ZINC PLT

MSRP: 320.36

Part Code: 050

Weight(lbs): 2.266


Weight(kg): 1.028

Weight(gm): 1028

Size: 2"X 1-1/2"SOC(2"SPG)

Color: GRAY

Material: CPVC

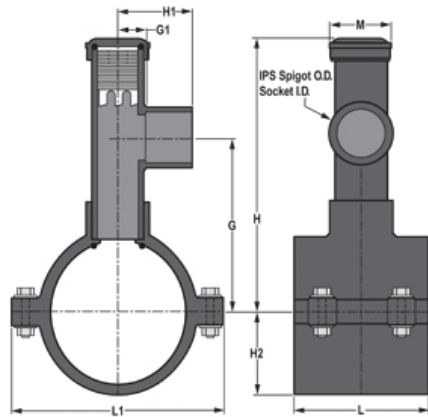

L = 2-7/16

G = 4-1/2

G1 = 1-1/4

H = 8-1/2

H1 = 2-11/16

H2 = 1-1/2

M = 2-7/8

L1 = 3-7/16

Connection Saddle x Socket (Spigot)

Hardware Zinc Plated

O-Ring FKM

NOTE Not intended To Convey Or Dispense Water For Human Consumption Through Drinking Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

