

Part No: HT3-291C

Schedule 80 PVC & CPVC

Hot-Tap Saddle

Desc: 2-1/2X1-1/2 CPVC HOT TAP SDLE FKM ZNC BT

MSRP: 330.97

Part Code: 050

Weight(lbs): 2.632


Weight(kg): 1.194

Weight(gm): 1194

Size: 2-1/2X1-1/2SOC(2"SPG)

Color: GRAY

Material: CPVC

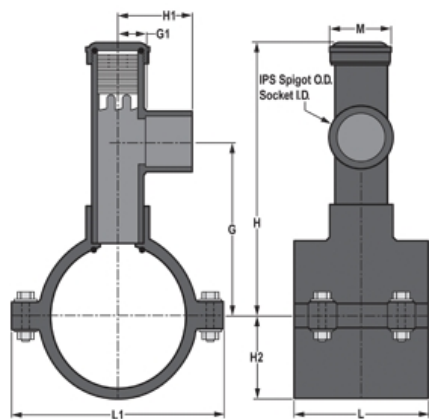

L = 4-1/8 **G** = 4-13/16 **G1** = 1-1/4 **H** = 8-13/16 **H1** = 2-11/16
H2 = 1-3/4 **M** = 2-7/8 **L1** = 4-1/8

Connection Saddle x Socket (Spigot)

Hardware Zinc Plated

O-Ring FKM

NOTE Not intended To Convey Or
Dispense Water For Human
Consumption Through Drinking
Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

