

Part No: HT3-419C

Schedule 80 PVC & CPVC

Hot-Tap Saddle

Desc: 4X1-1/2 CPVC HOT TAP SDLE FKM ZN PLTD BT

MSRP: 386.31

Part Code: 050

Weight(lbs): 3.481


Weight(kg): 1.579

Weight(gm): 1579

Size: 4"X 1-1/2"SOC(2"SPG)

Color: GRAY

Material: CPVC

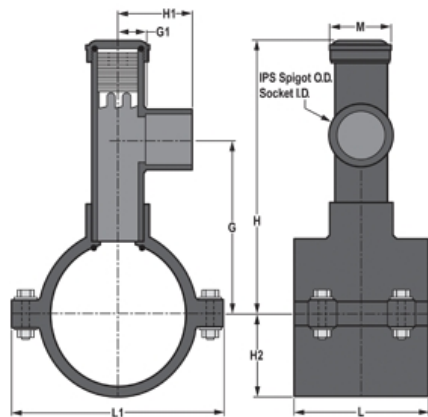

L = 4-1/8

G = 5-1/4

G1 = 1-1/4

H = 9-5/8

H1 = 2-11/16

H2 = 2-5/8

M = 2-7/8

L1 = 5-13/16

Connection Saddle x Socket (Spigot)

Hardware Zinc Plated

O-Ring FKM

NOTE Not intended To Convey Or Dispense Water For Human Consumption Through Drinking Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

