

Part No: HT3-574C

Schedule 80 PVC & CPVC

Hot-Tap Saddle

Desc: 8X3/4 CPVC HOT TAP SDDLE FKM ZINC BOLT

MSRP: 266.74

Part Code: 050

Weight(lbs): 9.738


Weight(kg): 4.417

Weight(gm): 4417

Size: 8"X 3/4"SOC(1"SPG)

Color: GRAY

Material: CPVC

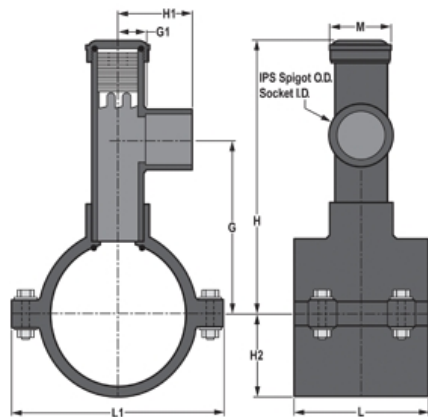

M = 2

L1 = 10-1/16

L = 8-1/2

G = 6-3/4

G1 = 1

H = 9-5/16

H1 = 2

H2 = 4-7/8

Connection Saddle x Socket (Spigot)

Hardware Zinc Plated

O-Ring FKM

NOTE Not intended To Convey Or
Dispense Water For Human
Consumption Through Drinking
Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

