

Part No: HT3S-416C

Schedule 80 PVC & CPVC

Hot-Tap Saddle

Desc: 4X3/4 CPVC HOT TAP SADDLE FKM S/S BOLT

MSRP: 341.37

Part Code: 050

Weight(lbs): 1.773


Weight(kg): 0.804

Weight(gm): 804

Size: 4"X 3/4"SOC(1"SPG)

Color: GRAY

Material: CPVC

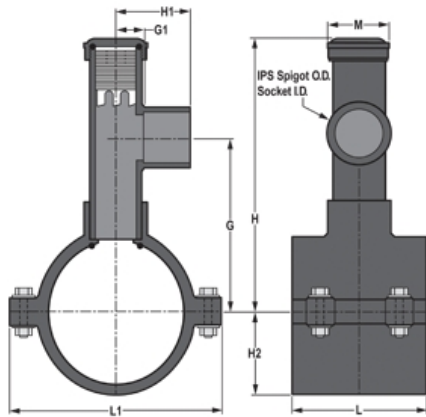

M = 2

L1 = 5-13/16

L = 3

G = 4-11/16

G1 = 1

H = 7-5/16

H1 = 2

H2 = 2-5/8

Connection Saddle x Socket (Spigot)

Hardware SS316

O-Ring FKM

NOTE Not intended To Convey Or
Dispense Water For Human
Consumption Through Drinking
Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

