

Part No: HT3S-419C

Schedule 80 PVC & CPVC

Hot-Tap Saddle

Desc: 4X1-1/2 CPVC HOT TAP SADDLE FKM S/S BOLT

MSRP: 601.47

Part Code: 050

Weight(lbs): 3.481


Weight(kg): 1.579

Weight(gm): 1579

Size: 4"X1-1/2"SOC(2"SPG)

Color: GRAY

Material: CPVC

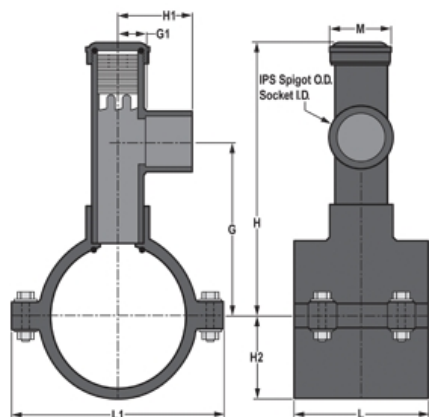

L = 4-1/8

G = 5-1/4

G1 = 1-1/4

H = 9-5/8

H1 = 2-11/16

H2 = 2-5/8

M = 2-7/8

L1 = 5-13/16

Connection Saddle x Socket (Spigot)

Hardware SS316

O-Ring FKM

NOTE Not intended To Convey Or
Dispense Water For Human
Consumption Through Drinking
Or Cooking

Cutter Brass

Type Hot-Tap

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

