

Part No: IJ-140-010P

Flanges & Cut-In Kit

Flange Cut-In Kit

Desc: 14X1 PP INSULATING JOINT CLASS 150

MSRP: 3401.7

Part Code: 016

Weight(lbs): 50.034


Weight(kg): 22.695

Weight(gm): 22695

Size: 14

Color: WHITE

Material: Polypropylene

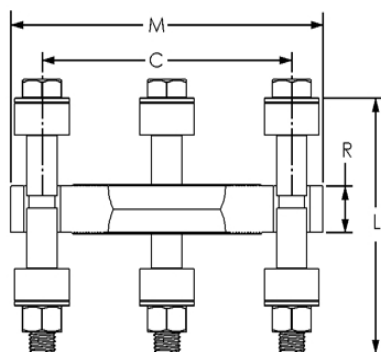

Type Insulating Joint
Pressure Rating 300 psi @ 73° F
Connection Class 150

Bolt Size = 1

No of Bolts = 12

C = 18-3/4

L = 6-1/2

M = 21

R = 1

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

