

Part No: LF1002-C

Lab Specialty

Lab Fixture

Desc: CPVC LAB FIXTURE DECK-MOUNT W/BV EPDM

MSRP: 331.87

Part Code: 219

Weight(lbs): 0.606


Weight(kg): 0.275

Weight(gm): 275

Size:

Color: GRAY

Material: CPVC

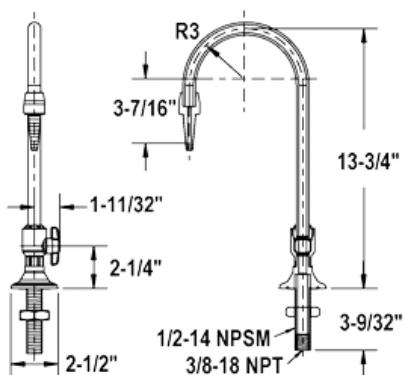

Type Deck Mount Lab Fixture W/Valve
-Direct Flow

Connection Fixture

O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

