

Part No: LF2003-C

Lab Specialty

Lab Fixture

Desc: CPVC LAB FIXTURE PNL-MNT W/BALL VLV FKM

MSRP: 554.62

Part Code: 219

Weight(lbs): 0.642

Weight(kg): 0.291

Weight(gm): 291

Size:


Color: GRAY

Material: CPVC

Type Panel Mount Lab Fixture
W/Valve-Direct Flow

Connection Fixture

O-Ring EPDM

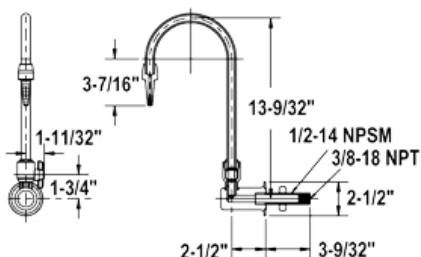

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

