

Part No: LF400

Lab Specialty

Lab Fixture

Desc: PVC SERRATED TIP SOCKET

MSRP: 4.27

Part Code: 218

Weight(lbs): 0.053

Weight(kg): 0.024

Weight(gm): 24


Size:

Color: GRAY

Material: PVC

Type Straight Serrated Tip - Accessory

Connection Fixture

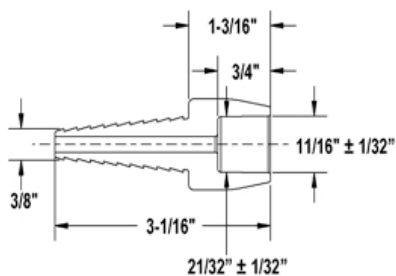

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

