

**Part No:** LFGN

**Lab Specialty**

**Lab Fixture**

**Desc:** PVC LAB FIXTURE GOOSENECK

**MSRP:** 30.63

**Part Code:** 218

**Weight(lbs):** 0.243

**Weight(kg):** 0.11

**Weight(gm):** 110


**Size:** 3/8

**Color:** GRAY

**Material:** PVC

**Type** Gooseneck (3/8") - Accessory

**Connection** Fixture

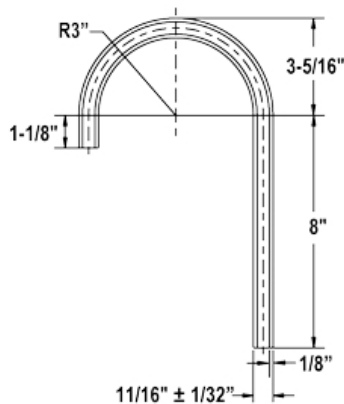

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

