

Part No: M851-120

Flanges & Cut-In Kit

Molded

Desc: 12PVC ONE-PC FLG SOC BOLT PATTERN

MSRP: 1114.12

Part Code: 081

Weight(lbs): 18.188

Weight(kg): 8.25


Weight(gm): 8250

Size: 12

Color: GRAY

Material: PVC

Connection Socket (One Piece - Multi Bolt Pattern)

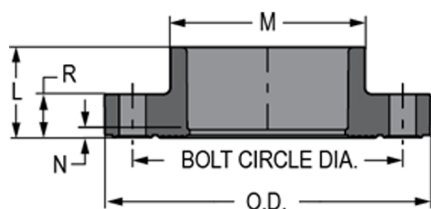

L = 6-5/8

O.D. = 19

M = 14

N = 5/8

R = 1-13/16

Bolt Circle Dia. = 15-3/4

No of Bolts = 12

Bolt Size = 7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

