

Part No: P093-040

LabWaste®

Elastomer No-Hub Coupling

Desc: 4 FKM TRANS COUP IPS TO PLN KIMAX;IPS

MSRP: 488.18

Part Code: 171

Weight(lbs): 0.514


Weight(kg): 0.233

Weight(gm): 233

Size: 4

Color:

Material: SS316/Rubber

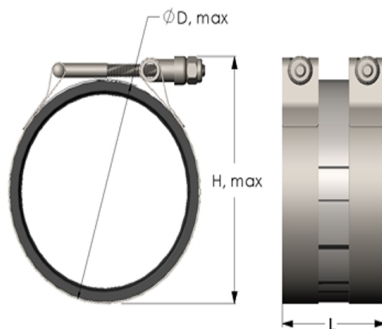

Type No-Hub Coupling

Connection IPS Clamp Joint x IPS Clamp Joint

Elastomer FKM

D = 4-13/16

H = 5-1/4

L = 2-1/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

