

Part No: P096-040C

LabWaste®

Coupling/Bushing

Desc: 4 CPVC LABWASTE GROOVED COUP GROOVEXSOC

MSRP: 203.18

Part Code: 169

Weight(lbs): 1.336

Weight(kg): 0.606

Weight(gm): 606


Size: 4"

Color: GRAY

Material: CPVC

Type Grooved Coupling

Connection Groove x Soc

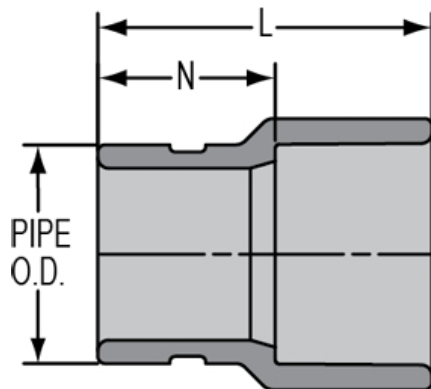

L = 4- 1/2

N = 2- 1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

