

Part No: P160M-040S

DWV

Floor Drain/Floor Cleanout

Desc: 4X6 PVC FLOOR DRAIN SS GRATE W/COLLAR

MSRP: 1112.03

Part Code: 054

Weight(lbs): 3.596

Weight(kg): 1.631


Weight(gm): 1631

Size: 4 X 6

Color: WHITE

Material: PVC

Type Floor Drain W/SS Adj Top
W/Round Grate & Membrane
Collar

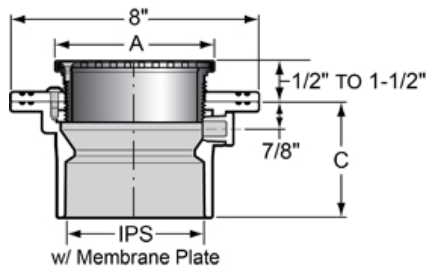

A, Nom = 6

C = 3-3/4

IPS = 4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

