

Part No: P309-030

DWV

Bend/Ell

Desc: 3 PVC DWV STREET L/S 1/4 BEND HUBXSPIGOT

MSRP: 52.98

Part Code: 051

Weight(lbs): 1.138

Weight(kg): 0.516

Weight(gm): 516


Size: 3"

Color: WHITE

Material: PVC

Type Long Sweep 1/4 Bend, Street

Connection Hub x Spigot

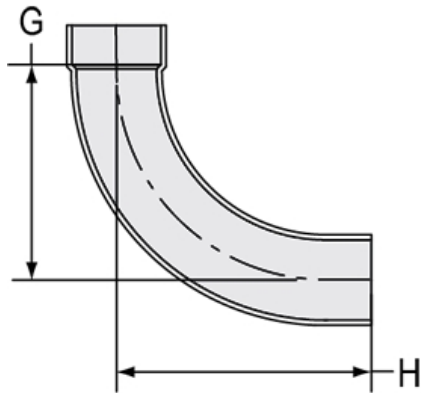

G = 4-1/16

H = 5-9/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

