

Part No: P327-040C

LabWaste®

Bend/Ell

Desc: 4 CPVC LW DOUBLE 1/4 BEND HUBXHUBXHUB

MSRP: 281.32

Part Code: 160

Weight(lbs): 0.216


Weight(kg): 0.098

Weight(gm): 98

Size: 4

Color: GRAY

Material: CPVC

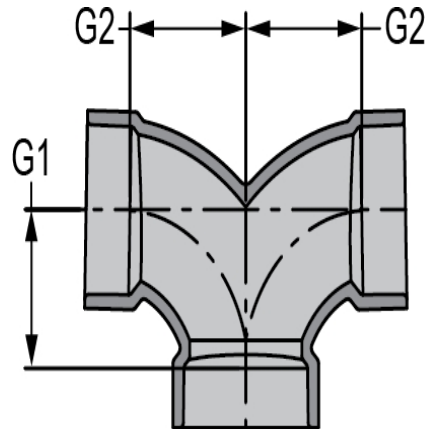

G1 = 3-7/8

G2 = 3-7/8

Type Double 1/4 Bend

Connection All Hub

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

