

**Part No:** P602-040

**DWV**

**Wye**

**Desc:** 4 PVC DWV STREET WYE SPGXHUBXHUB

**MSRP:** 105.08

**Part Code:** 051

**Weight(lbs):** 3.02

**Weight(kg):** 1.37

**Weight(gm):** 1370


**Size:** 4"

**Color:** WHITE

**Material:** PVC

**Type** Street Wye

**Connection** Spig x Hub x Hub

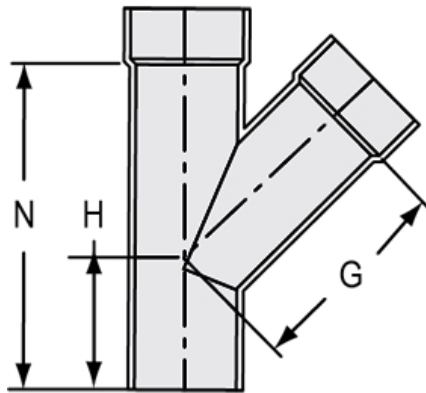

**G** = 6-7/16

**H** = 3-1/2

**N** = 9-15/16

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

