

Part No: P705-020C

LabWaste®

Trap

Desc: 2 CPVC LABWASTE S-TRAP HUBXHUB

MSRP: 206.82

Part Code: 160

Weight(lbs): 1.25

Weight(kg): 0.567

Weight(gm): 567


Size: 2"

Color: GRAY

Material: CPVC

Type S-Trap

Connection Hub x Hub

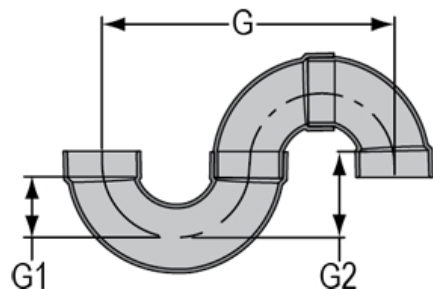

G = 10- 1/2

G1 = 2- 3/8

G2 = 3-1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

