

Part No: P705-040C

LabWaste®

Trap

Desc: 4 CPVC LABWASTE S-TRAP HUBXHUB

MSRP: 681.74

Part Code: 160

Weight(lbs): 6.799

Weight(kg): 3.084

Weight(gm): 3084


Size: 4"

Color: GRAY

Material: CPVC

Type S-Trap

Connection Hub x Hub

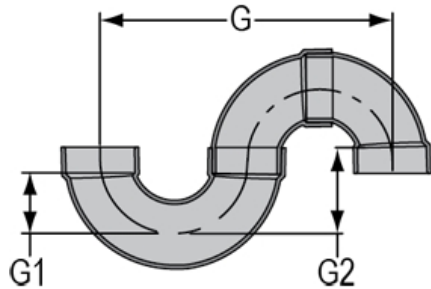

G = 17-3/4

G1 = 3-3/4

G2 = 5-9/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

