

Part No: P705R-015C

LabWaste®

Trap

Desc: 1-1/2 CPVC LABWASTE RUNNING TRAP HUBXHUB

MSRP: 148.21

Part Code: 160

Weight(lbs): 0.741

Weight(kg): 0.336

Weight(gm): 336


Size: 1 1/2"

Color: GRAY

Material: CPVC

Type Running Trap

Connection Hub x Hub

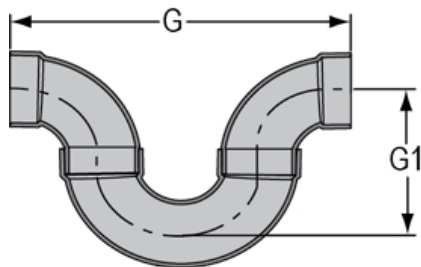

G = 7- 7/8

G1 = 3- 13/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

