

Part No: P706X-080

DWV

Trap

Desc: 8 PVC DWV P-TRAP HUBXHUB

MSRP: 1035.07

Part Code: 051

Weight(lbs): 25.466

Weight(kg): 11.551

Weight(gm): 11551


Size: 8"

Color: WHITE

Material: PVC

Type P-Trap

Connection Hub x Hub

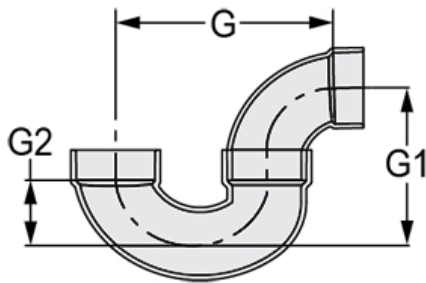

G = 22-9/16

G1 = 16- 1/2

G2 = 6

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

