

Part No: P706X-080C

LabWaste®

Trap

Desc: 8 CPVC LABWASTE P-TRAP HUBXHUB

MSRP: 1756.41

Part Code: 159

Weight(lbs): 32.937

Weight(kg): 14.94

Weight(gm): 14940


Size: 8"

Color: GRAY

Material: CPVC

Type P-Trap

Connection Hub x Hub

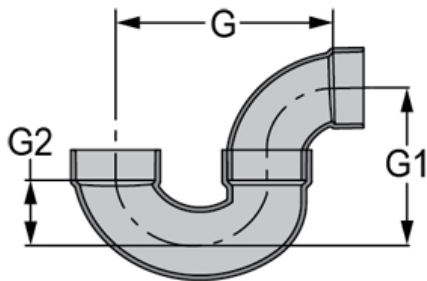

G = 22-9/16

G1 = 16- 1/2

G2 = 6

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

