

Part No: P720-030C

LabWaste®

Trap

Desc: 3 CPVC LW DRUMTRAP HXH

MSRP: 1019.78

Part Code: 160

Weight(lbs): 6.46

Weight(kg): 2.93

Weight(gm): 2930


Size: 3"

Color: GRAY

Material: CPVC

Type Drum Trap

Connection Hub x Hub

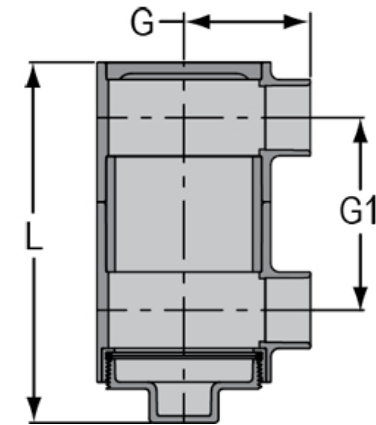

G = 4- 1/2

G1 = 6- 3/4

L = 13- 7/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

