

Part No: P720-040C

LabWaste®

Trap

Desc: 4 CPVC LW DRUMTRAP HXH

MSRP: 1170.36

Part Code: 160

Weight(lbs): 7.064

Weight(kg): 3.204

Weight(gm): 3204


Size: 4"

Color: GRAY

Material: CPVC

Type Drum Trap

Connection Hub x Hub

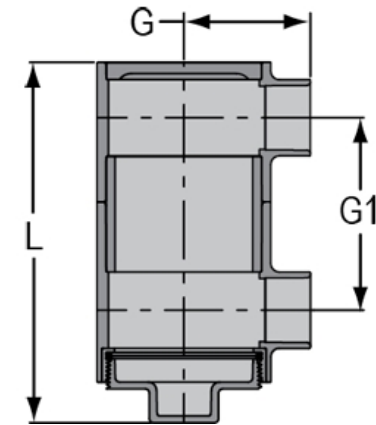

G = 4-3/8

G1 = 8-1/4

L = 15-11/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

