

Part No: P815KO-040

DWV

Closet Flange

Desc: 4X4/4X3 PVC DWV FLUSH CLOSET FLG W/KO

MSRP: 36.19

Part Code: 051

Weight(lbs): 0.734

Weight(kg): 0.333

Weight(gm): 333


Size: 4"X4" or 4"X3"

Color: WHITE

Material: PVC

Type Flush Closet Flange with Knockout

Connection Fits Over 3" Pipe or Inside 4" Pipe

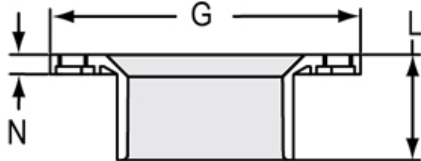

G = 7- 1/32

L = 2- 3/8

N = 15/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

