

Part No: S110-30

Compression & Repair Fitting Compression Couplings

Desc: 3 PVC COMPRESSION COUPLING

MSRP: 57.64

Part Code: 024

Weight(lbs): 3.208

Weight(kg): 1.455

Weight(gm): 1455

Size: 3"


Color: WHITE

Material: PVC

Connection Gasket x Gasket

Type Standard

Gasket Buna-N

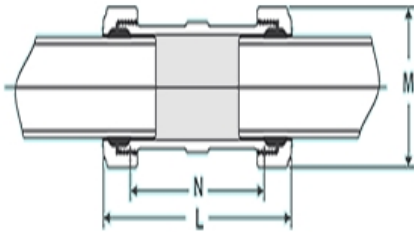

N = 6-3/16

M = 5-1/2

L = 9-5/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

