

Part No: S110-40G

Compression & Repair Fitting Compression Couplings

Desc: 4 PVC COMPRESSION COUPLING

MSRP: 111.86

Part Code: 024

Weight(lbs): 5.71

Weight(kg): 2.59

Weight(gm): 2590

Size: 4


Color: GRAY

Material: PVC

Connection Gasket x Gasket

Type Standard

Gasket EPDM

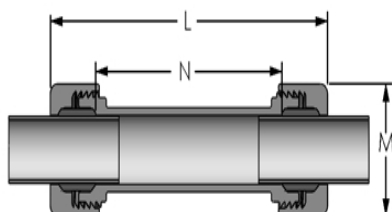

L = 11-9/16

M = 6-11/16

N = 7-3/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

