

**Part No:** S118-40T

**EverTUFF® TURF™**

**Repair Couplings**

**Desc:** 4 PVC REPAIR COUP CL315 SPIGOTXSOC

**MSRP:** 205.44

**Part Code:** 031

**Weight(lbs):** 6.832

**Weight(kg):** 3.099

**Weight(gm):** 3099

**Size:** 4 PVC REPAIR COUP CL315 S

**Color:** BLUE

**Material:** PVC


**Connection** Spigot x Socket

**Type** Repair Coupling

**O-Ring** EPDM

**Pressure Rating** Class 315

**NOTE** T = Travel

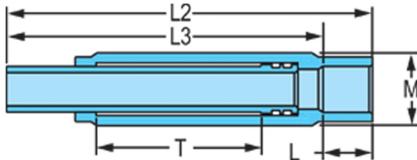

**L** = 2-1/4

**L2** = 14-7/8

**L3** = 12-9/16

**M** = 5-3/4

**T** = 6-3/16

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

