

Part No: S119-12T

EverTUFF® TURF™

Repair Couplings

Desc: 1-1/4 PVC REPAIR COUP CL315 SOCXSOC

MSRP: 38.48

Part Code: 031

Weight(lbs): 1.012

Weight(kg): 0.459

Weight(gm): 459

Size: 1-1/4 PVC REPAIR COUP CL3

Color: BLUE

Material: PVC


Connection Socket x Socket

Type Repair Coupling

O-Ring EPDM

Pressure Rating Class 315

NOTE T = Travel

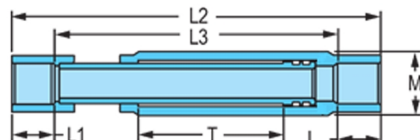

L = 1

L1 = 1-1/4

L2 = 10-3/16

M = 2-7/16

T = 4-1/16

L3 = 7-15/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

