

Part No: S119-15T

EverTUFF® TURF™

Repair Couplings

Desc: 1-1/2 PVC REPAIR COUP CL315 SOCXSOC

MSRP: 41.87

Part Code: 031

Weight(lbs): 1.166

Weight(kg): 0.529

Weight(gm): 529

Size: 1-1/2 PVC REPAIR COUP CL3

Color: BLUE

Material: PVC


Connection Socket x Socket

Type Repair Coupling

O-Ring EPDM

Pressure Rating Class 315

NOTE T = Travel

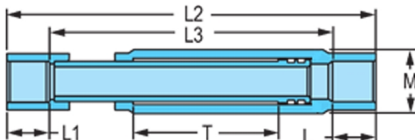

L = 1-1/8

L3 = 8-3/16

L1 = 1-3/8

L2 = 10-11/16

M = 2-11/16

T = 3-13/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

