

Part No: S1500-30

Valves

Compression Swing Check

Desc: 3 PVC COMPRESSION SWING CHECK VALVE

MSRP: 133.73

Part Code: 026

Weight(lbs): 5.055

Weight(kg): 2.293

Weight(gm): 2293

Size: 3"

Color: WHITE


Material: PVC

Type Compression Swing Check

Connection Compression

Body Color White

Pressure Rating 150 psi @ 73° F Full Flow (Open)
75 psi Back Pressure (Closed)

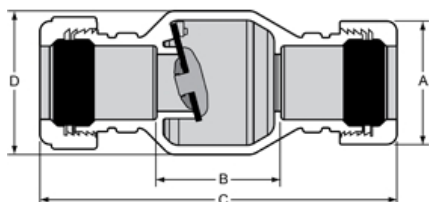

A = 5- 7/16

B = 4- 9/16

C = 12- 3/8

D = 5-23/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

