

Part No: S1520-60FSR

Valves

Swing & Spring Check

Desc: 6 PVC UTILIY SWING CHECK VLV SRTHD EPDM

MSRP: 373.41

Part Code: 026

Weight(lbs): 14.158

Weight(kg): 6.422

Weight(gm): 6422

Size: 6"


Color: WHITE

Material: PVC

Type Utility Swing Check

Connection SR Fipt

Body Color White

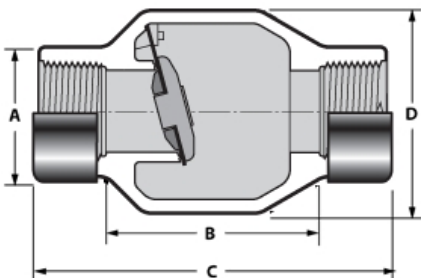

A = 7-11/16

B = 11- 5/16

C = 14-7/8

D = 9- 1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

