

Part No: S1520C20FSR

Valves

Swing & Spring Check

Desc: 2 PVC CL UTILITY SWNG CHK VLV SRTHD EPDM

MSRP: 92.56

Part Code: 026

Weight(lbs): 1.199


Weight(kg): 0.544

Weight(gm): 544

Size: 2"

Color: CLEAR

Material: PVC

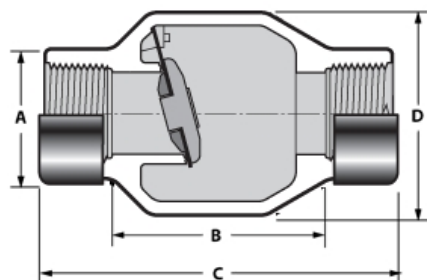

Type Utility Swing Check
Connection SR Fipt
Body Color Clear
Pressure Rating 150 psi @ 73° F Full Flow (Open)
 75 psi Back Pressure (Closed)

A = 3-1/16

B = 4-1/16

C = 6-1/16

D = 4- 1/4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

