

Part No: S1520C40F

Valves

Swing & Spring Check

Desc: 4 PVC CL UTILITY SWNG CHK VALVE THD EPDM

MSRP: 162.14

Part Code: 026

Weight(lbs): 4.605


Weight(kg): 2.089

Weight(gm): 2089

Size: 4"

Color: CLEAR

Material: PVC

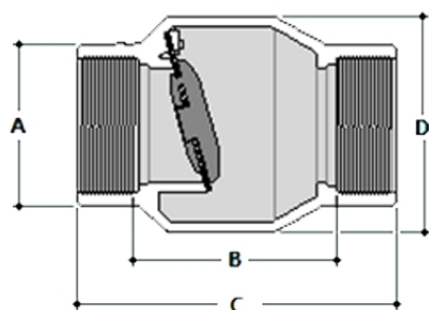

Type Utility Swing Check

Connection Fipt

Body Color Clear

Pressure Rating 150 psi @ 73° F Full Flow (Open)
75 psi Back Pressure (Closed)

A = 5- 1/4

B = 7-1/8

C = 9-15/16

D = 6- 3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

