

Part No: S1580-05F

Valves

Swing & Spring Check

Desc: 1/2 PVC UTILITY SPRNG CHK VALVE THD EPDM

MSRP: 55.16

Part Code: 026

Weight(lbs): 0.359


Weight(kg): 0.163

Weight(gm): 163

Size: 1/2"

Color: WHITE

Material: PVC

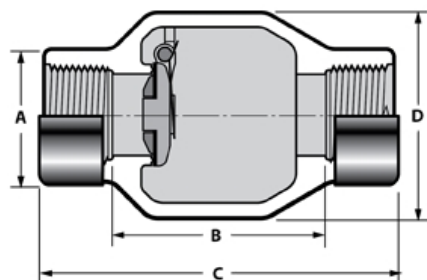

Type Utility Spring Check
Connection Fipt
Body Color White
Pressure Rating 150 psi @ 73° F Full Flow (Open)
 75 psi Back Pressure (Closed)

A = 1- 3/8

B = 2- 5/8

C = 4- 3/32

D = 2- 5/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.
- L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; ± 1/4 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.
- W** = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

