

Part No: S1580-15F

Valves

Swing & Spring Check

Desc: 1-1/2 PVC UTILITY SPRNG CHK VLV THD EPDM

MSRP: 52.69

Part Code: 026

Weight(lbs): 0.741


Weight(kg): 0.336

Weight(gm): 336

Size: 1-1/2"

Color: WHITE

Material: PVC

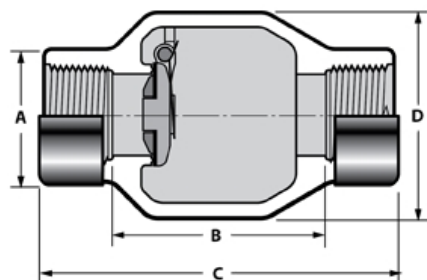

Type Utility Spring Check

Connection Fipt

Body Color White

Pressure Rating 150 psi @ 73° F Full Flow (Open)
75 psi Back Pressure (Closed)

A = 2- 7/16

B = 3-13/16

C = 5-11/16

D = 3- 3/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.
- L** = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; $\pm 1/4$ inch.
- N** = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.
- W** = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

