

Part No: S1580-20F

Valves

Swing & Spring Check

Desc: 2 PVC UTILITY SPRING CHECK VLVE THD EPDM

MSRP: 75.56

Part Code: 026

Weight(lbs): 1.202


Weight(kg): 0.545

Weight(gm): 545

Size: 2"

Color: WHITE

Material: PVC

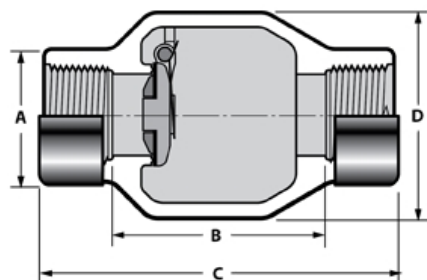

Type Utility Spring Check
Connection Fipt
Body Color White
Pressure Rating 150 psi @ 73° F Full Flow (Open)
 75 psi Back Pressure (Closed)

A = 3

B = 4-3/16

C = 6-1/16

D = 4- 1/4

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.
- L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; ± 1/4 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.
- W** = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

