

Part No: S1580-40F

Valves

Swing & Spring Check

Desc: 4 PVC UTILITY SPRING CHECK VLVE THD EPDM

MSRP: 198.51

Part Code: 026

Weight(lbs): 4.868


Weight(kg): 2.208

Weight(gm): 2208

Size: 4"

Color: WHITE

Material: PVC

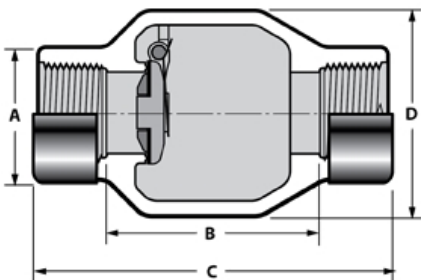

Type Utility Spring Check
Connection Fipt
Body Color White
Pressure Rating 150 psi @ 73° F Full Flow (Open)
 75 psi Back Pressure (Closed)

A = 5- 1/4

B = 7-1/8

C = 10

D = 6- 3/8

Fabricated Dimension References:

- G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.
- H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.
- J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.
- L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.
- M** = Outside diameter of socket/thread hub; ± 1/4 inch.
- N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.
- W** = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

