

Part No: S1580C15FSR

Valves

Swing & Spring Check

Desc: 1-1/2 PVC CL UTLTY SPR CK VLV SRTHD EPDM

MSRP: 99.41

Part Code: 026

Weight(lbs): 0.816


Weight(kg): 0.37

Weight(gm): 370

Size: 1-1/2"

Color: CLEAR

Material: PVC

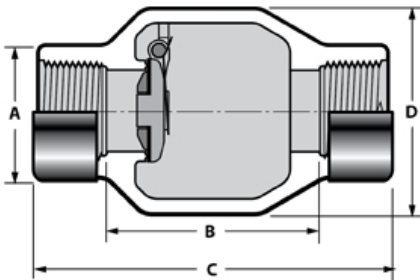

Type Utility Spring Check
Connection SR Fipt
Body Color Clear
Pressure Rating 150 psi @ 73° F Full Flow (Open)
 75 psi Back Pressure (Closed)

A = 2- 7/16

B = 3-13/16

C = 5-3/4

D = 3- 3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

